

MICREX-SE系列 印字表

NP1X3206-W NP1X3202-W		
GPP-FU2RY/GPP-FU2RT		
0.0	20 20	1.0
0.1	19 19	1.1
0.2	18 18	1.2
0.3	17 17	1.3
0.4	16 16	1.4
0.5	15 15	1.5
0.6	14 14	1.6
0.7	13 13	1.7
0.8	12 12	1.8
0.9	11 11	1.9
0.10	10 10	1.10
0.11	9 9	1.11
0.12	8 8	1.12
0.13	7 7	1.13
0.14	6 6	1.14
0.15	5 5	1.15
	4 4	
	3 3	
CO,B	2 2	
CO,A	1 1	

FCN插针40芯

NP1X3206-A		
GPP-FU3RY/GPP-FU3RT		
PORT9 (1.8)	20 20	PORT21 (2.4)
PORT10 (1.9)	19 19	PORT22 (2.5)
PORT11 (1.10)	18 18	PORT23 (2.6)
PORT12 (1.11)	17 17	PORT24 (2.7)
PORT13 (1.12)	16 16	PORT25 (2.8)
PORT14 (1.13)	15 15	PORT26 (2.9)
PORT15 (1.14)	14 14	PORT27 (2.10)
PORT16 (1.15)	13 13	PORT28 (2.11)
PORT17 (2.0)	12 12	PORT29 (2.12)
PORT18 (2.1)	11 11	PORT30 (2.13)
PORT19 (2.2)	10 10	PORT31 (2.14)
PORT20 (2.3)	9 9	PORT32 (2.15)
	8 8	CO,A4
	7 7	CO,A3
PORT1 (1.0)	6 6	PORT5 (1.4)
	5 5	CO,A2
PORT2 (1.1)	4 4	PORT6 (1.5)
PORT3 (1.2)	3 3	PORT7 (1.6)
	2 2	CO,A1
PORT4 (1.3)	1 1	PORT8 (1.7)

FCN插针40芯

NP1X6406-W					
GPP-FU4RY/GPP-FU4RT	GPP-FU5RY/GPP-FU5RT				
0.0	20 20	1.0	2.0	20 20	3.0
0.1	19 19	1.1	2.1	19 19	3.1
0.2	18 18	1.2	2.2	18 18	3.2
0.3	17 17	1.3	2.3	17 17	3.3
0.4	16 16	1.4	2.4	16 16	3.4
0.5	15 15	1.5	2.5	15 15	3.5
0.6	14 14	1.6	2.6	14 14	3.6
0.7	13 13	1.7	2.7	13 13	3.7
0.8	12 12	1.8	2.8	12 12	3.8
0.9	11 11	1.9	2.9	11 11	3.9
0.10	10 10	1.10	2.10	10 10	3.10
0.11	9 9	1.11	2.11	9 9	3.11
0.12	8 8	1.12	2.12	8 8	3.12
0.13	7 7	1.13	2.13	7 7	3.13
0.14	6 6	1.14	2.14	6 6	3.14
0.15	5 5	1.15	2.15	5 5	3.15
	4 4			4 4	
	3 3			3 3	
CO,B	2 2			CO,B	2 2
CO,A	1 1			CO,A	1 1

FCN插针40芯

NP1Y32T09P-A		
GPP-FU6RY/GPP-FU6RT		
PORT9 (12.8)	20 20	PORT21 (13.4)
PORT10 (12.9)	19 19	PORT22 (13.5)
PORT11 (12.10)	18 18	PORT23 (13.6)
PORT12 (12.11)	17 17	PORT24 (13.7)
PORT13 (12.12)	16 16	PORT25 (13.8)
PORT14 (12.13)	15 15	PORT26 (13.9)
PORT15 (12.14)	14 14	PORT27 (13.10)
PORT16 (12.15)	13 13	PORT28 (13.11)
PORT17 (13.0)	12 12	PORT29 (13.12)
PORT18 (13.1)	11 11	PORT30 (13.13)
PORT19 (13.2)	10 10	PORT31 (13.14)
PORT20 (13.3)	9 9	PORT32 (13.15)
	8 8	P,A4
	7 7	P,A3
PORT1 (12.0)	6 6	PORT5 (12.4)
	5 5	M,A2
PORT2 (12.1)	4 4	PORT6 (12.5)
PORT3 (12.2)	3 3	PORT7 (12.6)
	2 2	M,A1
PORT4 (12.3)	1 1	PORT8 (12.7)

FCN插针40芯

NP1Y32T09P1 NP1Y32U09P1		
GPP-FU7RY/GPP-FU7RT		
0.0	20 20	1.0
0.1	19 19	1.1
0.2	18 18	1.2
0.3	17 17	1.3
0.4	16 16	1.4
0.5	15 15	1.5
0.6	14 14	1.6
0.7	13 13	1.7
0.8	12 12	1.8
0.9	11 11	1.9
0.10	10 10	1.10
0.11	9 9	1.11
0.12	8 8	1.12
0.13	7 7	1.13
0.14	6 6	1.14
0.15	5 5	1.15
	4 4	
	3 3	
PO,B	2 2	MO,B
PO,A	1 1	MO,A

FCN插针40芯

NP1Y64T09P1 NP1Y64U09P1					
GPP-FU8RY/GPP-FU8RT	GPP-FU9RY/GPP-FU9RT				
0.0	20 20	1.0	2.0	20 20	3.0
0.1	19 19	1.1	2.1	19 19	3.1
0.2	18 18	1.2	2.2	18 18	3.2
0.3	17 17	1.3	2.3	17 17	3.3
0.4	16 16	1.4	2.4	16 16	3.4
0.5	15 15	1.5	2.5	15 15	3.5
0.6	14 14	1.6	2.6	14 14	3.6
0.7	13 13	1.7	2.7	13 13	3.7
0.8	12 12	1.8	2.8	12 12	3.8
0.9	11 11	1.9	2.9	11 11	3.9
0.10	10 10	1.10	2.10	10 10	3.10
0.11	9 9	1.11	2.11	9 9	3.11
0.12	8 8	1.12	2.12	8 8	3.12
0.13	7 7	1.13	2.13	7 7	3.13
0.14	6 6	1.14	2.14	6 6	3.14
0.15	5 5	1.15	2.15	5 5	3.15
	4 4			4 4	
	3 3			3 3	
PO,B	2 2	MO,B		P1,B	2 2
PO,A	1 1	MO,A		P1,A	1 1

FCN插针40芯

NP1W3206T NP1W3206U		
GPP-FU10RY/GPP-FU10RT		
0.0	20 20	1.0
0.1	19 19	1.1
0.2	18 18	1.2
0.3	17 17	1.3
0.4	16 16	1.4
0.5	15 15	1.5
0.6	14 14	1.6
0.7	13 13	1.7
0.8	12 12	1.8
0.9	11 11	1.9
0.10	10 10	1.10
0.11	9 9	1.11
0.12	8 8	1.12
0.13	7 7	1.13
0.14	6 6	1.14
0.15	5 5	1.15
	4 4	
	3 3	
	2 2	PO
CO	1 1	MO

FCN插针40芯

NP1F-HC2, NP1F-HC2MR NP1F-HC2MR1		
GPP-FU13RY/GPP-FU13RT		
B20	20 20	A20
B19	19 19	A19
B18	18 18	A18
B17	17 17	A17
B16	16 16	A16
B15	15 15	A15
B14	14 14	A14
B13	13 13	A13
B12	12 12	A12
B11	11 11	A11
B10	10 10	A10
B9	9 9	A9
B8	8 8	A8
B7	7 7	A7
B6	6 6	A6
B5	5 5	A5
B4	4 4	A4
B3	3 3	A3
B2	2 2	A2
B1	1 1	A1

FCN插针40芯

*由于此处的产品的信号名较复杂，所以套号码管上刻印了连接器针No.。

NP1W6406T NP1W6406U					
GPP-FU11RY/GPP-FU11RT	GPP-FU12RY/GPP-FU12RT				
0.0	20 20	1.0	2.0	20 20	3.0
0.1	19 19	1.1	2.1	19 19	3.1
0.2	18 18	1.2	2.2	18 18	3.2
0.3	17 17	1.3	2.3	17 17	3.3
0.4	16 16	1.4	2.4	16 16	3.4
0.5	15 15	1.5	2.5	15 15	3.5
0.6	14 14	1.6	2.6	14 14	3.6
0.7	13 13	1.7	2.7	13 13	3.7
0.8	12 12	1.8	2.8	12 12	3.8
0.9	11 11	1.9	2.9	11 11	3.9
0.10	10 10	1.10	2.10	10 10	3.10
0.11	9 9	1.11	2.11	9 9	3.11
0.12	8 8	1.12	2.12	8 8	3.12
0.13	7 7	1.13	2.13	7 7	3.13
0.14	6 6	1.14	2.14	6 6	3.14
0.15	5 5	1.15	2.15	5 5	3.15
	4 4			4 4	
	3 3			3 3	
CO,B	2 2			P1,B	2 2
CO,A	1 1			P1,A	1 1

FCN插针40芯

*为区别相同的信号名，此处的信号名可能与PLC制造商的使用手册中的记载有少许差异，请确认后订购。
*无信号名标记的引脚为未接线。

PLC线束

连接器转换、
分支线束

伺服马达
线束

触摸屏线束

RS-232C
线束





FA网络对应
线束

网线

矩形连接器
线束

同轴连接器
线束

测量通信
线束

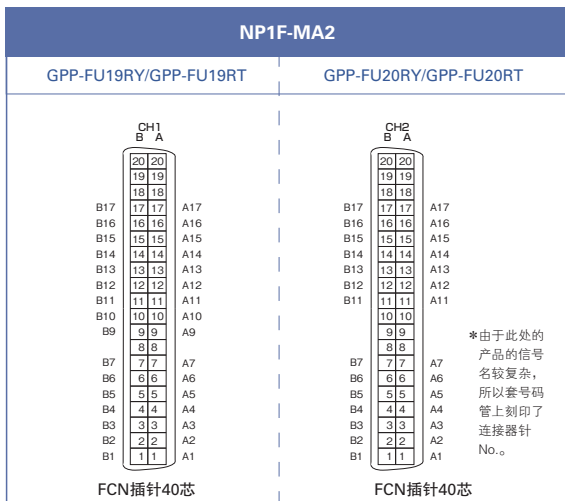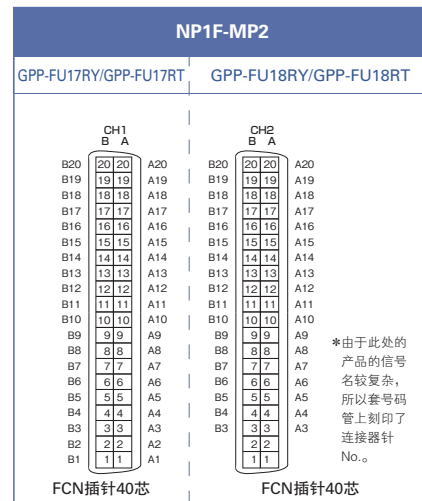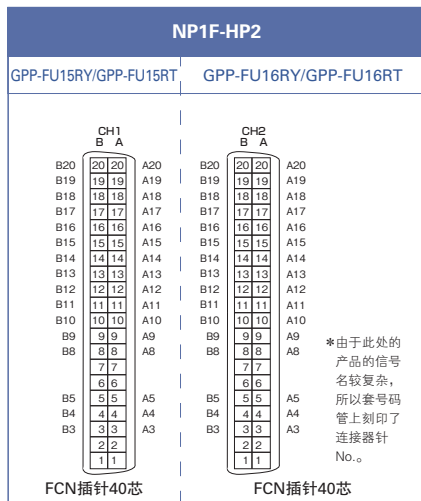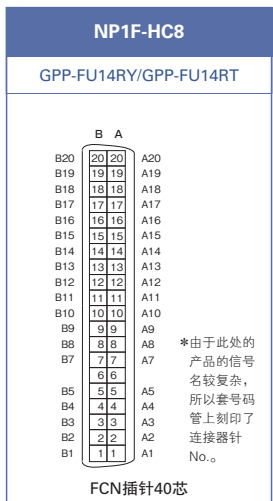

*为区别相同的信号名，此处的信号名可能与PLC制造商的使用手册中的记载有少许差异，请确认后再订购。
*无信号名标记的引脚为未接线。