


复位杆

RoHS

<MISUMI独创规格>

Type	肩部厚度 (T)	T公差	肩部垂直度
RP4TH	4mm	$\begin{smallmatrix} 0 \\ -0.05 \end{smallmatrix}$	
RP8TH	8mm	$\begin{smallmatrix} 0 \\ -0.1 \end{smallmatrix}$	
RP4TJ	4mm	$\begin{smallmatrix} 0 \\ -0.05 \end{smallmatrix}$	
RP8TJ	8mm	$\begin{smallmatrix} 0 \\ -0.1 \end{smallmatrix}$	

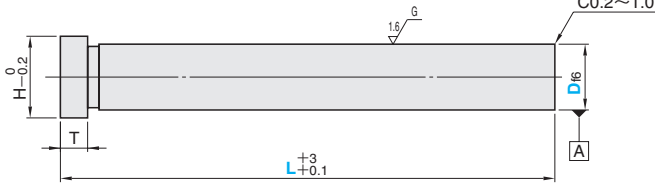

M 材质 SUJ2
H 硬度 58HRC~
高频淬火

⚠ 有时一端或两端带有中心孔。

 
H	Dφ6	型号		L 指定单位50mm
		Type	D	
11	8	肩部厚度4mm RP4TH (肩部垂直度:0.1) RP4TJ (肩部垂直度:0.05)	8	150 ~ 250
15	10		10	150 ~ 300
17	12		12	150 ~ 300
18	13		13	150 ~ 300
20	15		15	150 ~ 350
21	16		16	150 ~ 350
25	20	肩部厚度8mm RP8TH (肩部垂直度:0.1) RP8TJ (肩部垂直度:0.05)	20	150 ~ 400
30	25		25	150 ~ 450
35	30		30	150 ~ 450
15	10		10	150 ~ 300
17	12		12	150 ~ 300
18	13		13	150 ~ 300
20	15	肩部垂直度:0.1 RP8TH (肩部垂直度:0.1) RP8TJ (肩部垂直度:0.05)	15	150 ~ 350
21	16		16	150 ~ 350
25	20		20	150 ~ 500
30	25		25	150 ~ 500
35	30		30	150 ~ 500
40	35		35	300 ~ 500
45	40	肩部垂直度:0.1 RP8TH (肩部垂直度:0.1)	40	300 ~ 500
55	50		50	300 ~ 500



Alterations
追加加工



型号 — L — (MMC・SC)
RP4TH 20 — 300 — MMC8

Alterations	Code	Spec.	元/1Code																																
	MMC	加工肩部螺孔。 $l = M \times 2$ ⚠ 仅适用于 [RP4TJ]・[RP8TJ] <table><tr><th>D</th><th>选择螺纹M</th><th>D</th><th>选择螺纹M</th></tr><tr><td>8</td><td>4</td><td>25</td><td>8・10</td></tr><tr><td>10</td><td>4・5</td><td>30</td><td></td></tr><tr><td>12</td><td></td><td>35</td><td></td></tr><tr><td>13</td><td>5・6</td><td>40</td><td>8・10・12</td></tr><tr><td>15</td><td></td><td>50</td><td></td></tr><tr><td>16</td><td>6・8</td><td></td><td></td></tr><tr><td>20</td><td></td><td></td><td></td></tr></table>	D	选择螺纹M	D	选择螺纹M	8	4	25	8・10	10	4・5	30		12		35		13	5・6	40	8・10・12	15		50		16	6・8			20				询价 P.51
D	选择螺纹M	D	选择螺纹M																																
8	4	25	8・10																																
10	4・5	30																																	
12		35																																	
13	5・6	40	8・10・12																																
15		50																																	
16	6・8																																		
20																																			
	SC	如图所示, 肩部加工平行的平面(2面)。 (加工扳手槽平面) <table><tr><th>D</th><th>8</th><th>10</th><th>12</th><th>13</th><th>15</th><th>16</th><th>20</th><th>25</th><th>30</th><th>35</th><th>40</th><th>50</th></tr><tr><th>B</th><td>8</td><td>10</td><td>13</td><td>13</td><td>17</td><td>17</td><td>22</td><td>27</td><td>32</td><td>35</td><td>40</td><td>50</td></tr></table> ⚠ 仅适用于 [RP4TJ]・[RP8TJ]	D	8	10	12	13	15	16	20	25	30	35	40	50	B	8	10	13	13	17	17	22	27	32	35	40	50							
D	8	10	12	13	15	16	20	25	30	35	40	50																							
B	8	10	13	13	17	17	22	27	32	35	40	50																							

■适用螺旋弹簧的种类和外径(螺旋弹簧的详细情况, 请参阅 P.1147~1153, 1155~1162)

复位杆	复位杆用螺旋弹簧							螺旋弹簧		
D	SWY	SWU	SWR	SWS	SWN	X-SWU	X-SWR	SWF	SWL	SWM
8	φ 12.5	φ 14.5	φ 14.5	φ 14.5	φ 14.5	φ 14.5	φ 14.5	φ 18	φ 18	—
10	φ 16.5	φ 17	φ 17	φ 17	φ 17	φ 17	φ 17	φ 20・φ 22	φ 22	φ 22
12	φ 20.5	φ 21	φ 21	φ 21	φ 21	φ 21	φ 21	φ 25・φ 27	φ 27・φ 30	φ 27・φ 30
13										
15	φ 24.5	φ 26	φ 26	φ 26	φ 26	φ 26	φ 26	φ 30・φ 35	φ 35	φ 35
16										
20	φ 30	φ 31	φ 31	φ 31	φ 31	φ 31	φ 31	φ 40	φ 40	φ 40
25	φ 37	φ 37	φ 37	φ 37	φ 37	φ 37	φ 39	φ 50	φ 50	φ 50
30	φ 42	φ 43	φ 43	φ 44.5	—	φ 43	—	φ 60	—	—
35	—	—	φ 50	φ 52		—	—	φ 70	φ 70	φ 70



Order
订货范例

型号 — L
RP4TH 20 — 300



Delivery
交货期

•RP4TH・RP8TH
库存品

•RP4TJ・RP8TJ

3 天发货

⚠ 隔日上海・广州发货
(17:00前订购的库存品可当日发货。)
⚠ 数量≥51时, 请另询交货期。

⚠ 上海・广州发货
⚠ 数量≥51时, 请另询交货期。

型号	D \ L	单 价 (元)							
		150	200	250	300	350	400	450	500
肩部厚度4mm RP4TH (肩部垂直度:0.1)	8				—		—	—	—
	10								
	12								
	13								
	15								
	16								
	20								
	25								
	30								
	肩部厚度8mm RP8TH (肩部垂直度:0.1)	10						—	
12									
13									
15									
16									
20									
25									
30									
35									
40		—	—	—					
50									

型号	D	L	单价 (元)						
			150	200	250	300	350	400	450
肩部厚度4mm RP4TJ (肩部垂直度:0.05)	8					—			
	10						—		
	12							—	
	13								—
	15								
	16								
	20								
	25								
	30								
	35								
肩部厚度8mm RP8TJ (肩部垂直度:0.05)	10								
	12								
	13								
	15								
	16								
	20								
	25								
	30								
	35								
	40								