

リターンピン ー全長指定・タップ穴付タイプー

复位杆

ー全長指定・带螺孔型ー

RoHS




全長指定
带螺孔型



<MISUMI独创规格>

Type	肩部厚度(T)	T公差	L公差	肩部垂直度
RP4TLM	4mm	-0.05	$+0.5$ $+0.1$	$\perp 0.1$ A
RP8TLM	8mm	-0.1		
RP10TLM	10mm	-0.1		
RP4TVM	4mm	-0.05	$L \leq 200 \dots +0.2$ $L > 200 \dots +0.3$ $+0.1$	$\perp 0.05$ A
RP8TVM	8mm	-0.1		
RP4TVM	4mm	-0.05		
RP8TVM	8mm	-0.1	$L \leq 200 \dots +0.02$ $L > 200 \dots +0.05$ 0	$\perp 0.02$ A
RP4TVM	4mm	-0.05		
RP8TVM	8mm	-0.1		

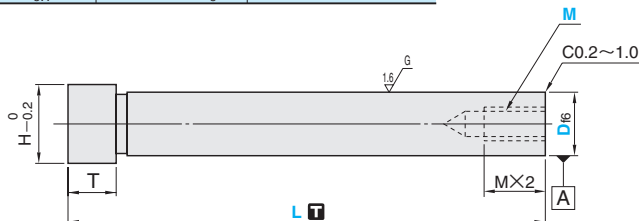

M 材质 SUJ2
H 硬度 58HRC~
高频淬火

有时肩部端面带有中心孔。

H	D ϕ	Type	D	L 指定单位0.1mm	M
11	8	RP4TLM (肩部垂直度:0.1)	8	35.0~250.0	4
15	10		10	35.0~300.0	4・5
17	12		12	35.0~300.0	4・5
18	13		13	35.0~300.0	4・5
20	15	RP4TVM (肩部垂直度:0.05)	15	35.0~350.0	5・6
21	16		16	35.0~350.0	6・8
25	20		20	50.0~400.0	6・8・10・12
30	25		25	50.0~450.0	8・10・12・16
35	30	RP8TLM (肩部垂直度:0.1)	30	50.0~450.0	8・10・12・16
15	10		10	35.0~300.0	4・5
17	12		12	35.0~300.0	4・5
18	13		13	35.0~300.0	4・5
20	15	RP8TVM (肩部垂直度:0.05)	15	35.0~350.0	5・6
21	16		16	35.0~350.0	6・8
25	20		20	50.0~400.0	6・8・10・12
30	25		25	50.0~450.0	8・10・12・16
35	30	RP10TLM (肩部垂直度:0.1)	30	50.0~450.0	8・10・12・16
40	35		40	100.0~500.0	8・10・12・16
45	40		45	100.0~500.0	8・10・12・16
55	50		50	100.0~500.0	8・10・12・16

H	D ϕ	Type	D	L 指定单位0.01mm	M
11	8	RP4TLM (肩部垂直度:0.02)	8	35.0~250.00	4
15	10		10	35.0~300.00	4・5
17	12		12	35.0~300.00	4・5
18	13		13	35.0~300.00	4・5
20	15	RP4TVM (肩部垂直度:0.02)	15	35.0~350.00	5・6
21	16		16	35.0~350.00	6・8
25	20		20	50.0~400.00	6・8・10・12
30	25		25	50.0~450.00	8・10・12・16
35	30	RP8TLM (肩部垂直度:0.02)	30	50.0~450.00	8・10・12・16
15	10		10	35.0~300.00	4・5
17	12		12	35.0~300.00	4・5
18	13		13	35.0~300.00	4・5
20	15	RP8TVM (肩部垂直度:0.02)	15	35.0~350.00	5・6
21	16		16	35.0~350.00	6・8
25	20		20	50.0~400.00	6・8・10・12
30	25		25	50.0~450.00	8・10・12・16
35	30	RP10TLM (肩部垂直度:0.02)	30	50.0~450.00	8・10・12・16
40	35		40	100.0~500.00	8・10・12・16
45	40		45	100.0~500.00	8・10・12・16
55	50		50	100.0~500.00	8・10・12・16



Alterations
追加加工



型号 — L — M — (MMC・SC)
RP4TLM 30 — 200.0 — M8 — MMC8

Alterations	Code	Spec.	元/1Code
	MMC	加工肩部螺孔。 选择螺纹M $\ell = M \times 2$	询价 P.51
	SC	如图所示, 肩部加工平行的平面(2面)。 (加工扳手槽平面)	



Order
订货范例

型号 — L — M
RP4TLM 20 — 199.0 — M8



Delivery
交货期

3 天 发 货

上海・广州发货
数量 ≥ 51 时, 请另询交货期。

型号	D	L	35.0 150.0	150.1 200.0	200.1 250.0	250.1 300.0	300.1 350.0	350.1 400.0	400.1 450.0	450.1 500.0
肩部厚度4mm RP4TLM (肩部垂直度:0.1)	8									
	10									
	12									
	13									
	15									
	16									
	20									
	25									
	30									
	40									
肩部厚度8mm RP8TLM (肩部垂直度:0.1)	10									
	12									
	13									
	15									
	16									
	20									
	25									
	30									
	35									
	40									

询价 下述2种方法 P.51
Web报价 米思米报价 <http://cn.misumi-ec.com/>
Fax报价 021-6710-8687
不明之处, 请致电: 021-6710-8701

型号	D	L	50.0 200.0	200.1 250.0	250.1 300.0	300.1 350.0	350.1 400.0
肩部厚度10mm RP10TLM (肩部垂直度:0.1)	20						
	25						

型号	D	L	35.00 150.00	150.01 200.00	200.01 250.00	250.01 300.00	300.01 350.00	350.01 400.00	400.01 450.00
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	8								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	10								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	12								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	13								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	15								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	16								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	20								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	25								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	30								

询价 下述2种方法 P.51
Web报价 米思米报价 <http://cn.misumi-ec.com/>
Fax报价 021-6710-8687
不明之处, 请致电: 021-6710-8701

型号	D	L	35.00 150.00	150.01 200.00	200.01 250.00	250.01 300.00	300.01 350.00	350.01 400.00	400.01 450.00
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	8								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	10								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	12								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	13								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	15								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	16								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	20								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	25								
肩部厚度4mm RP4TVM (肩部垂直度:0.05)	30								

询价 下述2种方法 P.51
Web报价 米思米报价 <http://cn.misumi-ec.com/>
Fax报价 021-6710-8687
不明之处, 请致电: 021-6710-8701



Example
使用范例

带螺孔复位杆可在模具组装时或
维修时用螺栓固定。

