


 
 


相当于SKD61
+ 氮化处理
相当于SKD61

STRAIGHT EJECTOR PINS -STANDARD TYPE-

直推杆

—标准规格—


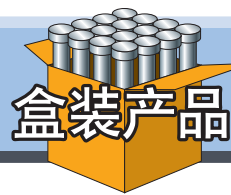
 
 


相当于
SKH51

STRAIGHT EJECTOR PINS -STANDARD TYPE-

直推杆

—标准规格—

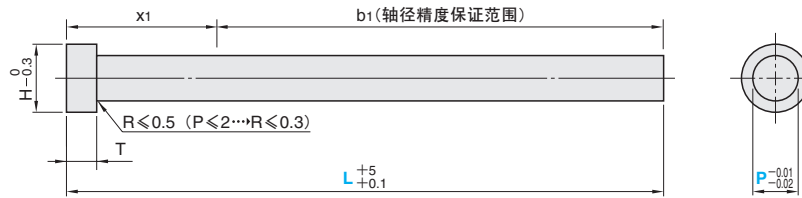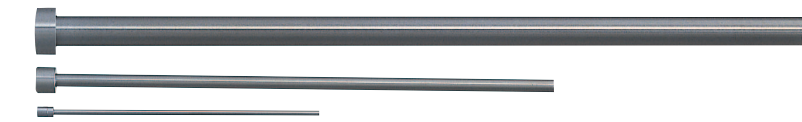

型号	肩部厚度	T公差	P公差	材质	硬度
50 PACK-C-EPN (50支装)	4mm (T4)	0 -0.02	-0.01 -0.02	相当于SKD61 + 氮化处理	表面: 900HV~ 材料: 40~45HRC
50 PACK-C-EPJ (50支装)	6mm (JIS)	0 -0.05			
50 PACK-C-EPD (50支装)	4mm (T4)	0 -0.02		相当于SKD61	50~55HRC

轴径精度保证范围 (b1=L-x1)
x1 max.40

H	T	型号			L 选择		
		PACK	Type	P			
3	4	50 PACK	C-EPN	1.5	100	150	200
4				2	100	150	200
5				2.5	100	150	200
6				3	100	150	200
7				3.5	100	150	200
8				4	100	150	200
9				5	100	150	200
				5.5	100	150	200

H	T	型号			L 选择		
		PACK	Type	P			
8	6	50 PACK	C-EPJ	4	100	150	200
9				5	100	150	200
				5.5	100	150	200

H	T	型号			L 选择	
		PACK	Type	P		
4	4	50 PACK	C-EPD	2	100	150
6				3	100	150



Order
订货范例

型号				L
PACK	Type	P		
(50支装)	50 PACK-C-EPN	3	—	100
(50支装)	50 PACK-C-EPJ	5	—	200
(50支装)	50 PACK-C-EPD	3	—	100



Delivery
交货期




库 存 品



Price
价格

询价联系方式:
WOS: <https://www.misumi-ec.com/cn/> P.19
TEL: 021-6710-8701 / FAX: 021-6710-8687 P.302

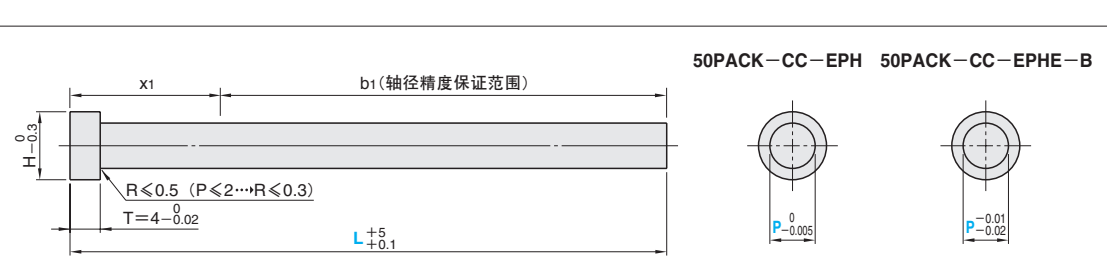

型号	肩部厚度	P公差
50PACK-CC-EPH (50支装)	4mm	0 -0.005
50PACK-CC-EPHE-B (50支装)	(T4)	-0.01 -0.02

轴径精度保证范围 (b1=L-x1)
x1 max.40

材质 相当于SKH51
硬度 58~60HRC

50支盒装

H	T	型号		L 选择
		Type	P	
3	4	50PACK-CC-EPH 50PACK-CC-EPHE-B	1	100 150 200
4			1.5	
5			2	
6			2.5	
			3	
			3.5	
7			4	

本产品以盒为单位进行销售。



Order
订货范例

型号				L
PACK	Type	P		
(50支装)	50PACK-CC-EPH	2	—	200



Delivery
交货期



库 存 品



Price
价格

询价联系方式:
WOS: <https://www.misumi-ec.com/cn/> P.19
TEL: 021-6710-8701 / FAX: 021-6710-8687 P.302