

相当于
SKH51
肩部厚度4mm


P·W⁰_{-0.01}
全长指定

RECTANGULAR EJECTOR PINS —TOTAL LENGTH SPECIFIED TYPE—

扁推杆
—全长指定型—

产品索引

P.37

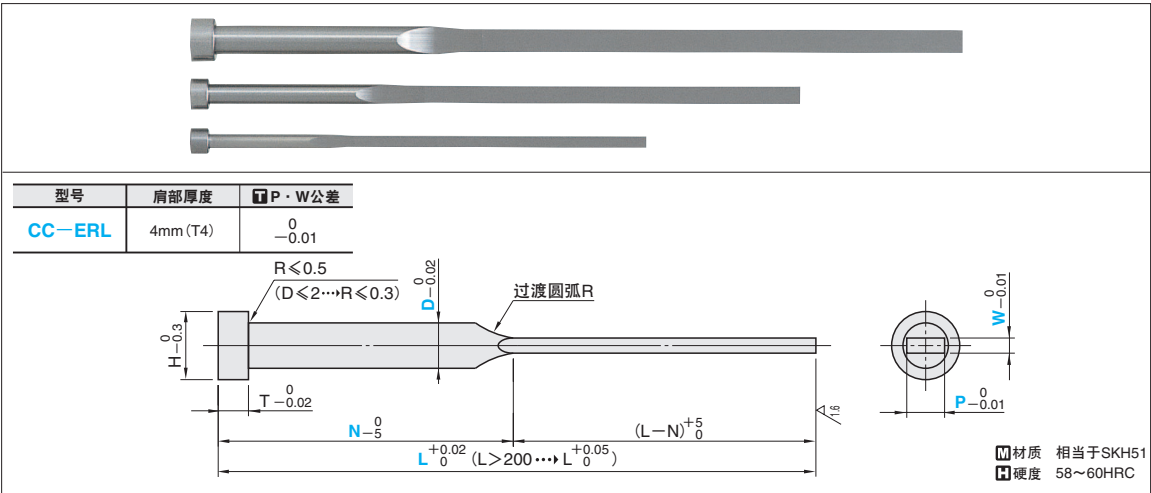

Order 订货范围
型号 — L — P — W — N
CC-ERL 8 —185.05 — P6.0 — W1.0 — N80

Delivery 交货期
3 天 发货

Price 价格
询价联系方式:
WOS: <https://www.misumi-ec.com/cn/> P.19
TEL: 021-6710-8701 / FAX: 021-6710-8687 P.302

Alterations 追加加工
型号 — L — P — W — N — (AKC·AWC...etc.)
CC-ERL 8 — 185.05 — P6.0 — W1.0 — N80 — AKC 0

Alterations	Code	Spec.
	AKC	AKC角度指定单位1° 0° ≤ AKC < 360
	AWC	AWC角度指定单位1° 0° ≤ AWC < 360
	ARC	ARC角度指定单位1° 0° ≤ ARC < 360

Alterations	Code	Spec.
	ADC	ADC角度指定单位1° 0° ≤ ADC < 360
	HC	HC尺寸指定单位0.1mm D+1 ≤ HC < H
	TC	TC尺寸指定单位0.1mm 2.0 ≤ TC < 4且4-T ≤ Lmax.-L L, N为指定尺寸 N尺寸缩短了(T-TC)

H	T	型号	Type	D	L 指定单位0.01mm	P	W	N 指定单位5mm
3				1.5	50.00 ~ 100.00 100.01 ~ 150.00	0.8 1.0 1.2	0.3 0.4 0.5 0.6	40 ~ 90 40 ~ 140
4				2	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00	1.0 1.2 1.5	0.4 0.5 0.6 0.7 0.8 1.0	40 ~ 90 40 ~ 140 40 ~ 190
5				2.5	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00	1.5 (2.0)	0.4 0.5 0.6 0.7 0.8 1.0 1.2 (1.5)	40 ~ 90 40 ~ 140 40 ~ 190
6				3	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00	2.0 (2.5)	0.4 0.5 0.6 0.7 0.8 1.0 1.2 (1.5) (2.0)	40 ~ 90 40 ~ 140 40 ~ 190
7				3.5	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	2.5 (3.0)	0.4 0.5 0.6 0.7 0.8 0.9 1.0 1.2 1.5 (2.0)	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
8				4	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	3.0 (3.5)	0.4 0.5 0.6 0.7 0.8 0.9 1.0 1.2 1.5 (2.0)	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
9				4.5	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	3.5 (4.0)	0.6 0.7 0.8 0.9 1.0 1.2 1.5 1.8 (2.0) (2.5)	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
10				5	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	4.0	0.6 0.7 0.8 0.9 1.0 1.2 1.5 1.8 2.0 2.5	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
11				5.5	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	4.5 (5.0)	0.8 0.9 1.0 1.2 1.5 1.8 2.0 (2.5)	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
14				6	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	5.0	0.8 0.9 1.0 1.2 1.5 1.8 2.0 2.5 3.0	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
15				6.5	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	6.0	0.8 0.9 1.0 1.2 1.5 1.8 2.0	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
17				7	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	6.0	0.8 0.9 1.0 1.2 1.5 1.8 2.0 2.5	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
14				8	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	6.0 7.0 7.5	0.8 0.9 1.0 1.2 1.5 1.8 2.0 2.5	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
15				8.5	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	7.0 8.0	0.8 0.9 1.0 1.2 1.5 1.8 2.0 2.5	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
17				10	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	8.0	0.8 1.0 1.2 1.5 1.8 2.0 2.5 1.0 1.2 1.5 1.8 2.0 2.5	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240
17				10.5	50.00 ~ 100.00 100.01 ~ 150.00 150.01 ~ 200.00 200.01 ~ 250.00	10.0	1.2 1.5 2.0	40 ~ 90 40 ~ 140 40 ~ 190 40 ~ 240

不能同时选择P·W尺寸“()”内的数值。 L-N ≥ 10