

自润滑中心导轨

—标准型(铜合金)—


自润滑调整滑板/小型自润滑滑板

—标准型(铜合金)/10mm型(铜合金)—




C—CGZ

■2螺栓孔型

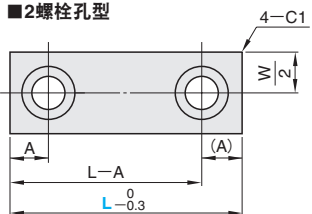

■3螺栓孔型

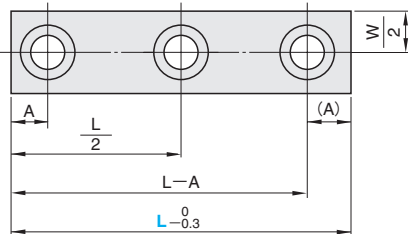

■螺栓孔规格表

W	T	d1	d2	t1
15	15	9.5	5.5	6
20	15	11	6.5	7
20	20			

型号	材质
C—CGZ	高强度黄铜 (CAC304) 镶嵌石墨

型号		T	L	螺栓孔数	A
Type	W	选择			
C—CGZ	15	15	40 50 60	2	7.5
			70 80 90 100	3	
	20	15	40 50 60 70 80 90	2	10
		20	100 110	3	
			120 130 140 150		



Order 订货范例

型号 — T — L

C—CGZ 15 — 15 — 40



Delivery 交货期

7 天 发货



Price 价格

 
询价联系方式:
WOS: <https://www.misumi-ec.com/cn/> P.19
TEL: 021-6710-8701 / FAX: 021-6710-8687 P.300




Alterations 追加加工

型号 — T — L — (NA)

C—CGZ 20 — 20 — 120 — NA




Alteration	Code	Spec.
	NA	不加工安装螺栓孔。

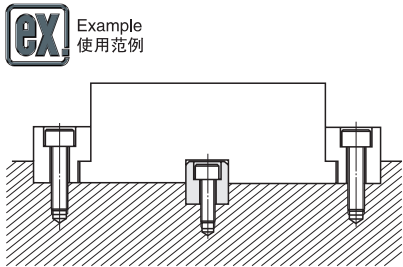



C—SAPZ

A=50·70时, 2螺栓孔型 A=80·100·120时, 3螺栓孔型

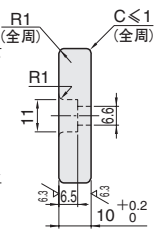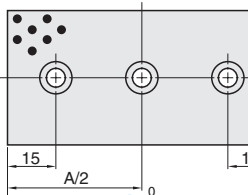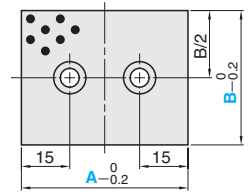


型号	材质
C—SAPZ	高强度黄铜 (CAC304) 镶嵌石墨

Type	A	B
C—SAPZ	50	30
		40
		30
		40
	70	30
		40
		50
		60
	80	40
		50
		60
		40
	100	50
		60
		40
		50
	120	40
		50
		60


Example 使用范例

(1) 螺栓固定型

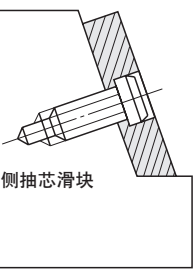


侧抽芯滑块




(2) 嵌入型

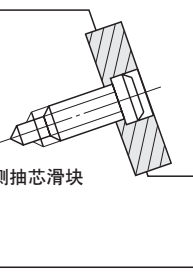


侧抽芯滑块

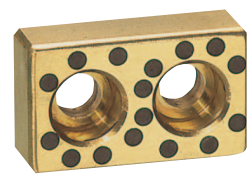

C—STZ

 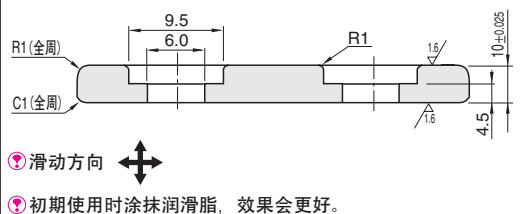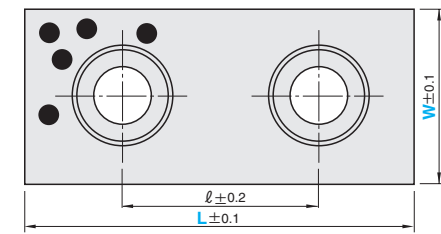

安装螺栓请另行购买, 推荐使用 CBS5—20

 

滑动方向

初期使用时涂抹润滑脂, 效果会更好。

型号	材质
C—STZ	高强度黄铜 (CAC304) 镶嵌石墨

ℓ	型号	W	L
14	C—STZ	15	30
20			40
30			50
50			75
14		18	30
20			40
30			50
50			75
14		22	30
20			40
30			50
50			75



Order 订货范例

型号 — L

C—SAPZ 70 — 40

C—STZ 18 — 50



Delivery 交货期

7 天 发货



Price 价格

询价联系方式:
WOS: <https://www.misumi-ec.com/cn/> P.19
TEL: 021-6710-8701 / FAX: 021-6710-8687 P.302