



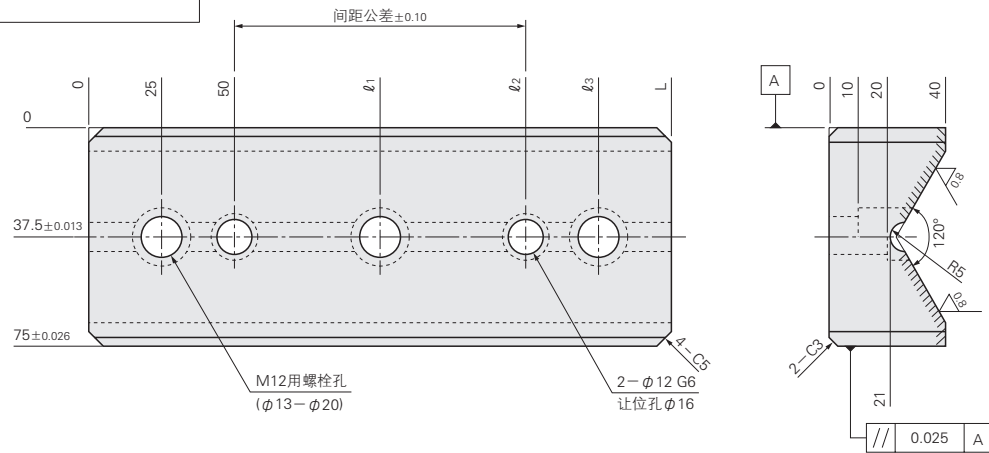

カムスライドガイド Vガイドタイプ  
斜楔V形导板 V导向型

U形滑块

CMG21

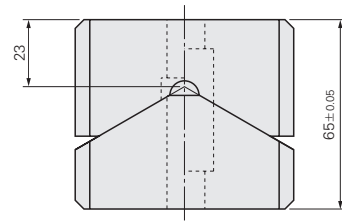

材质  
S45C  
//// 部 高频淬火  
40HRC以上

L	N 孔数	l <sub>1</sub>	l <sub>2</sub>	l <sub>3</sub>	NAAMS代码	Catalog No.	
						系列名	No.
150	2	—	100	125	G217515	CMG21	7515
200		—	150	175	G217520		7520
250	3	125	200	225	G217525		7525
300		150	250	275	G217530		7530

Order 订货范例

Catalog No. 系列名 No.  
CMG21 7515

Delivery 交货期



另 询交货期

Price 价格

询价联系方式:  
WOS: <https://www.misumi-ec.com/cn/> P.57  
TEL: 021-6710-8701 / FAX: 021-6710-8984 P.1663

V形滑块

CMG22  
CMG23

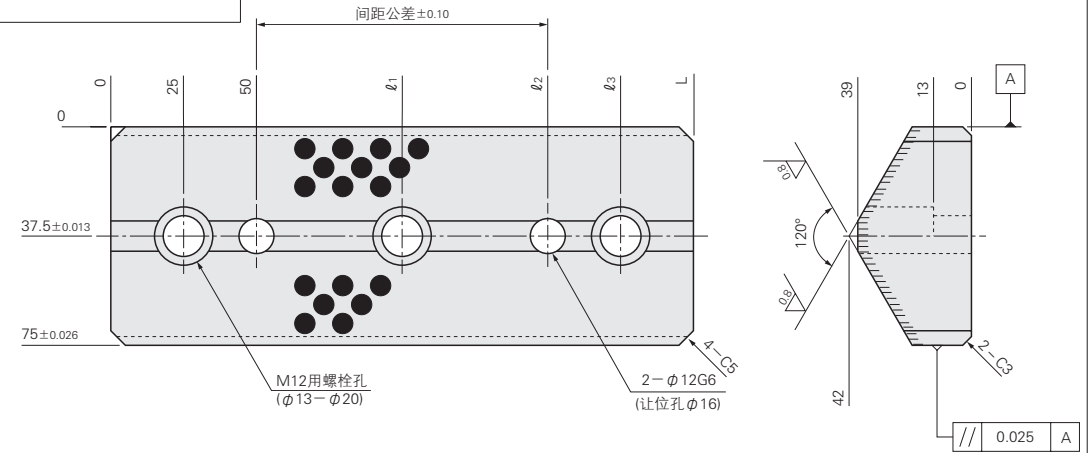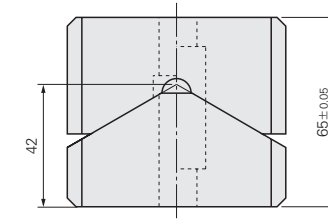

材质  
CMG22 S45C石墨(镶嵌)  
//// 部 高频淬火  
40HRC以上  
CMG23 高力黄铜  
石墨(镶嵌)

L	N 孔数	l <sub>1</sub>	l <sub>2</sub>	l <sub>3</sub>	NAAMS代码		Catalog No.	
					钢型	铜合金类型	系列名	No.
150	2	—	100	125	G227515	G237515	CMG22 CMG23	7515
200		—	150	175	G227520	G237520		7520
250	3	125	200	225	G227525	G237525		7525
300		150	250	275	G227530	G237530		7530

Order 订货范例

Catalog No. 系列名 No.  
CMG22 7515

Delivery 交货期

另 询交货期

Price 价格

询价联系方式:  
WOS: <https://www.misumi-ec.com/cn/> P.57  
TEL: 021-6710-8701 / FAX: 021-6710-8984 P.1663