

PLAIN GUIDE POST SETS — REMOVABLE POST · PRESS FIT POST —

模架用滑动导柱组件

— 装卸型 · 压入型 —

产品索引

P.49

— 自润滑 (固体润滑剂) —

— 滑动 —

RoHS 10


C-RZ




C-PZ



C-RD

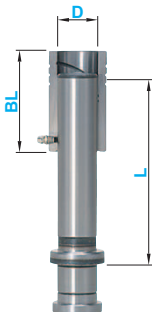

C-PD

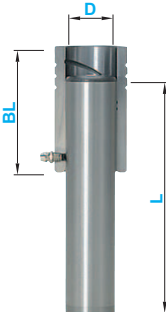


Catalog No.	构成零件	
	①	②
C-RZ	C-MRP	C-LDBZ
C-PZ	C-MSP	C-LDB
C-RD	C-MRP	C-LDB
C-PD	C-MSP	C-LDB


■ 导套安装方法 (粘接剂P.148)

C-LDBZ	LOCTITE 粘接	LOCTITE No.638 (LOC638)
C-LDB		

① C-MRP (P.143)

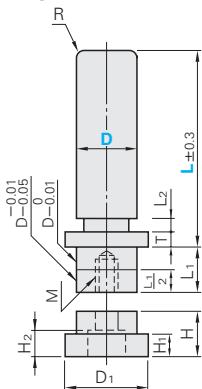


① C-MSP (P.143)

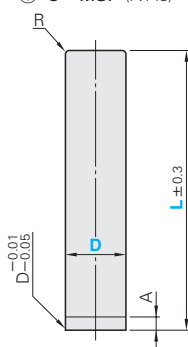

② C-LDBZ (P.145)



② C-LDB (P.145)

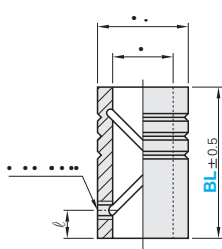

C-MRP										
D	D1	L1	L2	H	H1	H2	T	M	R	附属螺栓
20	28	15		14	7	8.5	5	8	2.0	CB 8-25
22	+0.025 +0.015	30	16				8	× 18	3.0	
25		35	18							
28	+0.030	36	20		16	8	10.5	10	10 × 22	CB10-30
32	+0.020	40	23	12						
38	+0.035	49	27		18	10	12.5	12	12 × 27	CB12-35
45	+0.025	55	32	15						

C-MSP			
D	A	R	
20		2.0	
22	+0.025 +0.015	4	3.0
25			
28	+0.030	5	3.5
32	+0.020		
38	+0.035	6	4.0
45	+0.025		

ℓ	d		C-LDBZ / C-LDB	
			D2	T
10	20		31	
	22	+0.037 +0.027	34	
	25		37	
	28	+0.047 +0.037	42	
15	32		46	
	38	+0.052 +0.042	54	
	45		62	
			0 -0.01	

Type	M 材质	H 硬度	A 附件
C-MRP	M SUJ2		
	H 58HRC~ (高频淬火)		
	M S45C (安装盖)		A 内六角螺栓 CB
C-MSP	M SUJ2		
	H 58HRC~ (高频淬火)		
C-LDBZ	M SUJ2		
	H 58HRC~ (高频淬火)		
C-LDB	M SUJ2		
	H 58HRC~ (高频淬火)		

Catalog No.		L										BL	
Type	D												
C—RZ C—RD	20	80	90	100	110	120	150				180	50	
	22	80	90	100	110	120						50 60	
	25	80	90	100	110	120	130					60 80	
	28	100			110	120	130	140	150	160			60 80
	32					120	130	140	150	160			80 100
	38							140	150	160	170	180	80 100
	45							140	150	160	170	180	100 120

Catalog No.		L												BL			
Type	D																
C—PZ C—PD	20	100	110	120	130	140	150	160	170	180					50		
	22			120	130		150	160	170	180					50	60	
	25			120	130	140	150	160	170	180					60	80	
	28					140	150	160	170	180	190	200			60	80	
	32							160	170	180	190	200	220	240	80	100	
	38									180	190	200	220	240	260	80	100
	45										180		200	220	240	260	100



Order
订货范例

Catalog No. — L — ② · BL
C-RZ20 — 120 — L50

订货符号 C-RZ 20 12 5
C-PZ 28 16 8



Delivery
交货期

库存品

隔日上海·广州发货 P.9
(17:00前订购的库存品可当日发货。)
数量≥51时, 请另询交货期。



Price
价格

询价联系方式:
WOS: <https://www.misumi.com.cn> P.17
TEL: 021-6710-8701 / FAX: 021-6710-8984 P.182