

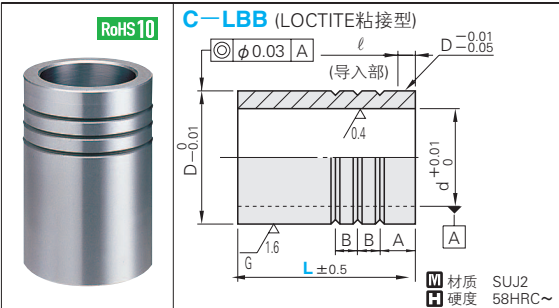


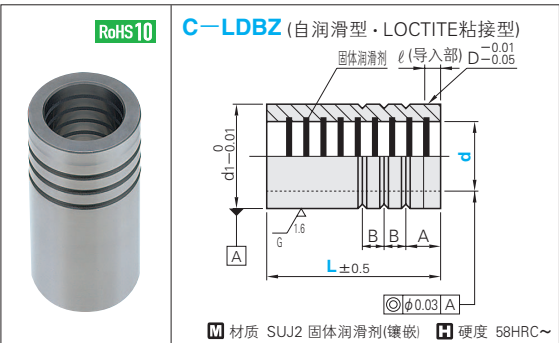

Catalog No.		L		
Type	PD			
C-LBB (LOCTITE粘接型)	20	50	60	
	22	50	60	
	25	60	80	
	28	60	80	100
	32		80	100
	38		80	100
	45		100	120
	50		100	120

请勿对导套进行冷缩配合。与深冷处理同样，残留奥氏体会转变为马氏体并膨胀，导套内、外径均变大，导致无法使用。

PD 适用导柱直径		C-LBB				
		d	D	ℓ	A	B
20	+0.025 +0.015	26	37	4	10	6
22		28	40			
25	+0.030 +0.020	31	45	5	12	7
28		36	50			
32	+0.035 +0.025	40	55	6	15	10
38		48	64			
45	±0.040 ±0.030	55	74			
50		60	83			

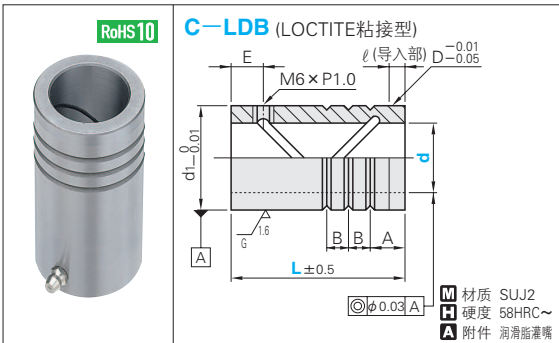

请勿对导套进行冷缩配合。与深冷处理同样，残留奥氏体会转变为马氏体并膨胀，导套内、外径均变大，导致无法使用。

Catalog No.		L		
Type	d			
C-LDBZ C-LDB	20	50		
	22	50	60	
	25	60	80	
	28	60	80	
	32		80	100
	38		80	100
	45		100	120

■粘接方法 (粘接剂P.148)

Catalog No.	粘接剂
C-LDBZ C-LDB	LOCTITE No.638 (LOC638)



Catalog No. — L

C-LBB 45 — 120
C-LDBZ 28 — 80




隔日上海・广州发货 P.9
(17:00前订购的库存品可当日发货。)

数量≥51时，请另询交货期。

C-LDB・C-LDBZ数量≥51时，请另询交货期。

询价联系方式：

WOS: <https://www.misumi.com.cn> P.17
TEL: 021-6710-8701 / FAX: 021-6710-8984 P.182

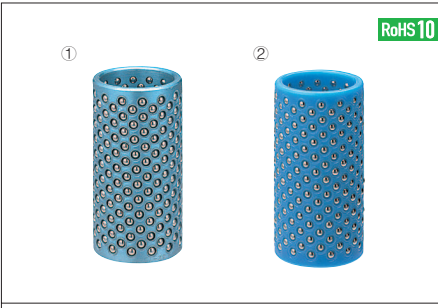

Catalog No.		L		
Type	PD			
C-MBSH (铝合金) C-MBJH (树脂)	20	50		
	22	50	60	
	25	60	80	
	28	60	80	100
	32		80	100
	38		80	100
	45		100	120
	50		100	120



Catalog No.		L		
Type	PD			
C-MBSM (铝合金) C-MBJM (树脂)	20	50		
	22	50	60	
	25	60	80	
	28	60	80	100
	32		80	100
	38		80	100
	45		100	120
	50		100	120

PD 适用导柱直径		外径 φD	内径 φD ₁	钢球直径 φd	钢球数			Catalog No.		
					C-MBSH C-MBJH	C-MBSM C-MBJM	比率	Type	PD	L
20	+0.025 +0.015	25.5	20.5	3	165	132	1.25	C-MBSH (铝合金) C-MBJH (树脂)	20	50
22		27.5	22.5		180	144	1.25		22	50
25		30.5	25.5		228	176	1.30		25	60
28	+0.030 +0.020	35.5	28.5	4	266	198	1.34	C-MBSM (铝合金) C-MBJM (树脂)	28	60
32		39.5	32.5		350	252	1.39		32	75
38		47.5	38.5		204	160	1.28		38	75
45	+0.035 +0.025	54.5	45.5	5	252	224	1.13		45	90
50		59.5	50.5		294	216	1.36		50	90
					350	270	1.30			
					238	200	1.19			
					294	240	1.23			
					336	240	1.40			
					400	300	1.33			
					378	264	1.43			
					450	330	1.36			



Order
订货范围



Delivery
交货期



Price
价格

询价联系方式：

WOS: <https://www.misumi.com.cn> P.17
TEL: 021-6710-8701 / FAX: 021-6710-8984 P.182