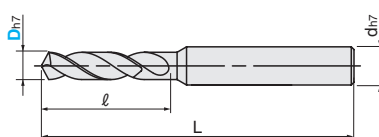


TiCN涂层粉末高速钢钻头(NACHI制造)

●立铣刀柄型 / 短刃型

-エンドミルシャンク/ショートタイプ-

SGESS																				
																				
材质	 			<table><tr><th>直径D</th><th>公差(h7)</th></tr><tr><td>1 ~ 3</td><td>0 -0.010</td></tr><tr><td>3.05 ~ 6</td><td>0 -0.012</td></tr><tr><td>6.1 ~ 10</td><td>0 -0.015</td></tr><tr><td>10.1 ~ 18</td><td>0 -0.018</td></tr><tr><td>18.5 ~ 20</td><td>0 -0.021</td></tr></table>		直径D	公差(h7)	1 ~ 3	0 -0.010	3.05 ~ 6	0 -0.012	6.1 ~ 10	0 -0.015	10.1 ~ 18	0 -0.018	18.5 ~ 20	0 -0.021	螺旋角为约30°。		
直径D	公差(h7)																			
1 ~ 3	0 -0.010																			
3.05 ~ 6	0 -0.012																			
6.1 ~ 10	0 -0.015																			
10.1 ~ 18	0 -0.018																			
18.5 ~ 20	0 -0.021																			
规格	  																			
	D1~1.9 D2~20																			
普通钢 (SS・SC钢)		合金钢 (SCM)		调质钢 (~45HRC)		高硬度钢 (50HRC~)		工具钢 (SKD,SKS)		不锈钢 (SUS)		铸铁 (FC,FCD)		铝 (Al)		铜 (Cu)				
◎		◎		◎				◎		○		○		○		○				

◎=量适合 ○=适合

型号 SGESS

直径 D	槽长 ℓ	全长 L	柄径	单价(元)
1	6	38	3	1支 2~4支 5~10支
1.05	6	38	3	
1.1	7	39	3	
1.15	7	39	3	
1.2	8	40	3	
1.25	8	40	3	
1.3	8	40	3	
1.35	9	41	3	
1.4	9	41	3	
1.45	9	41	3	
1.5	9	41	3	
1.55	10	42	3	
1.6	10	42	3	
1.65	10	42	3	
1.7	10	42	3	
1.75	11	43	3	
1.8	11	43	3	
1.85	11	43	3	
1.9	11	43	3	
1.95	12	44	3	
2	12	44	3	
2.05	12	44	3	
2.1	12	44	3	
2.15	13	45	3	
2.2	13	45	3	
2.25	13	45	3	
2.3	13	45	3	
2.35	13	45	3	
2.4	14	46	3	
2.45	14	46	3	
2.5	14	46	3	
2.55	14	46	3	
2.6	14	46	3	
2.65	14	46	3	
2.7	16	48	3	
2.75	16	48	3	
2.8	16	48	3	
2.85	16	48	3	
2.9	16	48	3	
2.95	16	48	3	
3	16	48	3	
3.05	18	50	4	
3.1	18	50	4	
3.15	18	50	4	
3.2	18	50	4	
3.25	18	50	4	
3.3	18	50	4	

直径 D	槽长 ℓ	全长 L	柄径	单价(元)
3.35	18	50	4	1支 2~4支 5~10支
3.4	20	52	4	
3.45	20	52	4	
3.5	20	52	4	
3.55	20	52	4	
3.6	20	52	4	
3.65	20	52	4	
3.7	20	52	4	
3.75	20	52	4	
3.8	22	54	4	
3.85	22	54	4	
3.9	22	54	4	
3.95	22	54	4	
4	22	54	4	
4.05	22	54	4	
4.1	22	54	4	
4.15	22	54	4	
4.2	22	54	4	
4.25	22	54	4	
4.3	24	56	4	
4.35	24	56	4	
4.4	24	56	4	
4.45	24	56	4	
4.5	24	56	4	
4.55	24	56	4	
4.6	24	56	4	
4.65	24	56	4	
4.7	24	56	4	
4.75	24	56	4	
4.8	26	58	4	
4.85	26	58	4	
4.9	26	58	4	
4.95	26	58	4	
5	26	58	4	
5.05	26	58	4	
5.1	26	58	4	
5.15	26	58	4	
5.2	26	58	4	
5.25	26	58	4	
5.3	26	58	4	
5.35	28	60	4	
5.4	28	60	4	
5.45	28	60	4	
5.5	28	60	4	
5.55	28	60	4	
5.6	28	60	4	
5.65	28	60	4	

直径 D	槽长 ℓ	全长 L	柄径	单价(元)
5.7	28	72	6	1支 2~4支 5~10支
5.75	28	72	6	
5.8	28	72	6	
5.85	28	72	6	
5.9	28	72	6	
5.95	28	72	6	
6	28	72	6	
6.1	31	75	8	
6.2	31	75	8	
6.3	31	75	8	
6.4	31	75	8	
6.5	31	75	8	
6.6	31	75	8	
6.7	31	75	8	
6.8	34	78	8	
6.9	34	78	8	
7	34	78	8	
7.1	34	78	8	
7.2	34	78	8	
7.3	34	78	8	
7.4	34	78	8	
7.5	34	78	8	
7.6	37	81	8	
7.7	37	81	8	
7.8	37	81	8	
7.9	37	81	8	
8	37	81	8	
8.1	37	81	8	
8.2	37	81	8	
8.3	37	81	8	
8.4	37	81	8	
8.5	37	81	8	
8.6	40	90	10	
8.7	40	90	10	
8.8	40	90	10	
8.9	40	90	10	
9	40	90	10	
9.1	40	90	10	
9.2	40	90	10	
9.3	40	90	10	
9.4	40	90	10	
9.5	40	90	10	
9.6	43	93	10	
9.7	43	93	10	
9.8	43	93	10	
9.9	43	93	10	
10	43	93	10	

直径 D	槽长 ℓ	全长 L	柄径	单价(元)
10.1	43	100	12	1支 2~4支 5~10支
10.2	43	100	12	
10.3	43	100	12	
10.4	43	100	12	
10.5	43	100	12	
10.6	43	100	12	
10.7	47	104	12	
10.8	47	104	12	
10.9	47	104	12	
11	47	104	12	
11.1	47	104	12	
11.2	47	104	12	
11.3	47	104	12	
11.4	47	104	12	
11.5	47	104	12	
11.6	47	104	12	
11.7	47	104	12	
11.8	47	104	12	
11.9	51	108	12	
12	51	108	12	
12.1	51	108	12	
12.2	51	108	12	
12.3	51	108	12	
12.4	51	108	12	
12.5	51	108	12	
12.6	51	108	12	
12.7	51	108	12	
12.8	51	108	12	
12.9	51	108	12	
13	51	108	12	
13.5	72	132	16	
14	72	132	16	
14.5	76	136	16	
15	76	142	20	
15.5	80	146	20	
16	80	146	20	
16.5	84	150	20	
17	84	150	20	
17.5	87	153	20	
18	87	153	20	
18.5	90	156	20	
19	90	164	25	
19.5	94	168	25	
20	94	168	25	

切削条件 P.479



Order
订货范例

SGESS 10

型号

直径(D)



Delivery
交货期

5

天 发货

20支以上交货期请另询。

